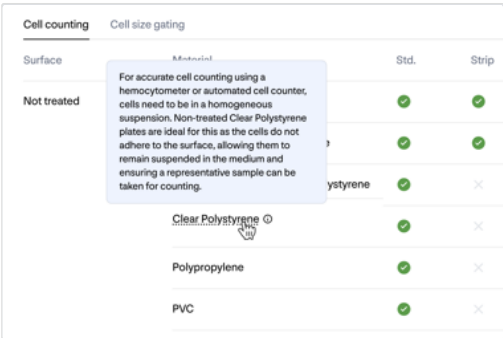


Tooltips | Annotations

All templates and components must be WCAG 2.2 compliant

Component Name	Tooltips
Figma Link	Link
Change Log	12/17 - Added annotations
Prototype / Interactions	Link
Screenshot	 <p>Tooltip used on table</p>

Component Rules:

- This component can be used on Table and Carousel - Product Carousel
 - For future state, we would recommend adding tooltip functionality to Text and Forms

Annotations:

Tooltip text box


Terms Applicable
The "bundled price" reflects a discount applied to the simultaneous purchase of specified, complementary products. This pricing structure is subject to change without prior notice.

Tooltip

- All breakpoints:
 - Width


- Fixed 340 px
- Title
 - Optional
 - Recommended max characters: 30
- Description
 - Required
 - No character limit

Triggers

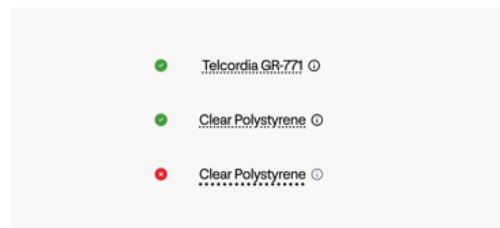

- A **tooltip trigger** is what the user will hover (desktop) or tap (tablet / mobile) on to show the tooltip
- Type sizes that can be triggers:
 - All Body sizes
 - No pre-titles
 - No headings
 - No custom sizes
- Info icon
 - Must match the color of the type
 - Size: 16px
 - Gap: 4px
- Underline
 - Dotted
 - [Decoration: skip ink](#)
 - Thickness: 12%
 - Offset: Auto

Alignment and positioning

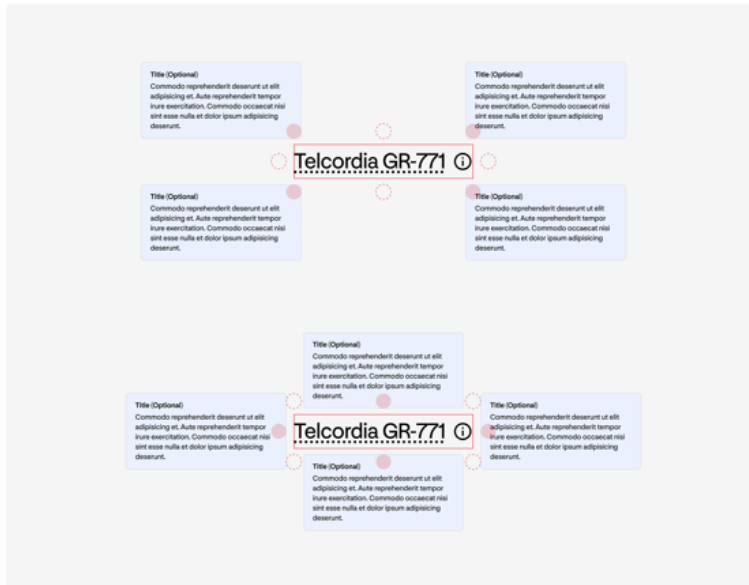

- Alignment

- The tooltip's alignment and positioning is based on the trigger element's location relative to the browser window's boundaries. Depending on the space available, the tooltip can position itself at multiple anchor points
 - By default, if space is available, the tooltip is aligned to the top-center. If space isn't available on the top, the tooltip repositions to be bottom-center aligned
 - If the trigger is positions closer to the browser window's corners, the top-left, top-right, bottom-left, and bottom-right anchor points can be used to position the tooltip

- Positioning

- Top and bottom: 12px from trigger element
- Left and right: 16px from trigger element